


3-2122145-4 | FMS-J-4-B-I-S1-48-IN99-48-SP

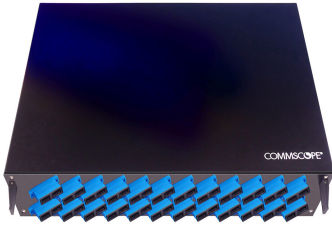

FMS Fiber Optic Termination/Splice Panel, 2U, 19 in, 48 SC/UPC, singlemode, OS2, black

Product Classification

| | |
|------------------------------|--------------------------|
| Regional Availability | India |
| Portfolio | CommScope® |
| Product Type | Fiber patch/splice panel |
| Product Series | FMS |

General Specifications

| | |
|--|------------------------------------|
| Functionality | Patching Splicing |
| Body Style | Symmetrical |
| Cable Exit Location | Rear, left side Rear, right side |
| Color | Black |
| Interface, front | SC/UPC |
| Fiber Color Code | TIA-598 |
| Rack Type | EIA 19 in |
| Rack Units | 2 |
| Shelf Movement | Sliding |
| Splice Trays Included, quantity | 4 |
| Splicing Type | Heat shrink, single fiber fusion |
| Total Ports, quantity | 48 |

Dimensions

| | |
|---------------|--------------------|
| Height | 88.9 mm 3.5 in |
| Width | 482.6 mm 19 in |
| Depth | 320 mm 12.598 in |

Material Specifications

| | |
|---------------|---------------|
| Finish | Powder coated |
|---------------|---------------|

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Fiber Type OS2

Insertion Loss, maximum 0.3 dB

Return Loss, minimum 45 dB

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|--|
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

