


760109470 | 360G2 Cartridge 12-LC-LS-AQ-PIGTAILS

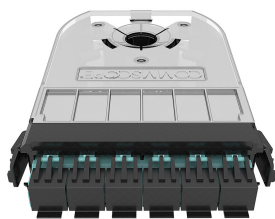

360G2 Multimode OM4 Fiber Cassette 12 LC, with pigtails, iPatch Ready

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with pigtails
Product Series	G2

General Specifications

Color, front	Aqua
Intelligence Type	iPatch® ready
Interface, front	LC/UPC
Interface, rear	Stranded pigtail
Shuttered	No
Total Ports, quantity, front	12

Dimensions

Height	25.908 mm 1.02 in
Width	94.996 mm 3.74 in
Depth	123.012 mm 4.843 in

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4
Insertion Loss, maximum	0.33 dB

Environmental Specifications

Qualification Standards	IEC 61753-1 TIA-568.3-D
Safety Standard	CE CSA UL

760109470 | 360G2 Cartridge 12-LC-LS-AQ-PIGTAILS

Packaging and Weights

Packaging quantity 1
Weight, net 0.098 kg | 0.215 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

