

TFP-24APRQ2DE3



TFP Fiber Optic Adapter Pack, 24-fiber, 2 pigtail assemblies, Multimode, LC, quad, right, aqua

Product Classification

Regional Availability	Asia Latin America North America
Portfolio	NETCONNECT®
Product Type	Fiber adapter pack with pigtails
Product Series	TFP

General Specifications


Application	For use with TFP panels
Adapter Color	Aqua
Adapters, quantity, front	6
Body Style	Quad Right orientation
Color, front	Black
Interface	LC/UPC
Pigtail Assembly Type	Color-coded, 900 µm Pigtail bundle
Pigtails Included, quantity	24
Total Fibers, quantity	24
Total Ports, quantity, front	24

Dimensions

Height	33.53 mm 1.32 in
Width	176.02 mm 6.93 in
Pigtail Length	3 m 9.843 ft

Ordering Tree

TFP-24APRQ2DE3

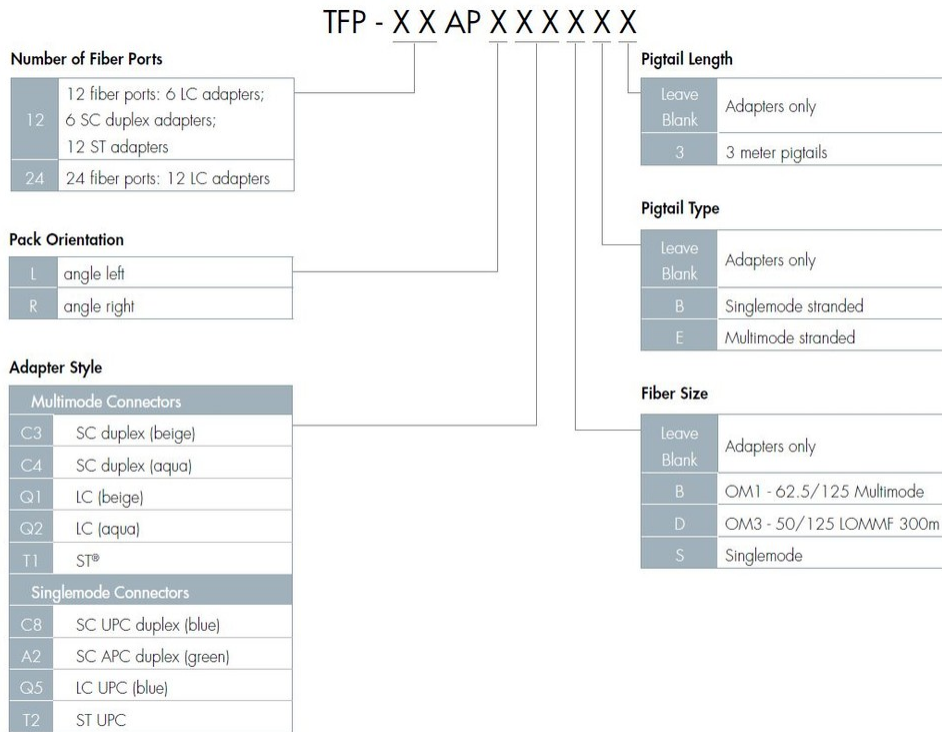

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM3
Insertion Loss, maximum	0.3 dB
Return Loss, minimum	20 dB

Environmental Specifications

Operating Temperature	0 °C to +70 °C (+32 °F to +158 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value

TFP-24APRQ2DE3

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

