


F3VMPMPAM

Base Product

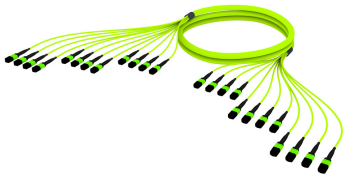

OM5 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Pre-terminated Trunk Cable, 144-Fiber, Low Smoke Zero Halogen B2ca

- LazrSPEED® WideBand extends the capability of OM4 across enough spectrum to support at least four low-cost wavelengths

OBSOLETE

This product was discontinued on: October 7, 2024

Replaced By:

U3VMPMPAM

Ultra Low Loss ULL LazrSPEED® 550 OM5 MPO(Unpinned) to MPO(Unpinned) Pre-terminated Trunk Cable, MPO12, 144-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration


General Specifications

Color, boot A	Black
Color, connector A	Lime green
Color, boot B	Black
Color, connector B	Lime green
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-12/UPC Female
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Lime green
Polarity	Method B (LL)

F3VMPMPAM

Fibers per Subunit, quantity	12
Total Fibers, quantity	144
Dimensions	
Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

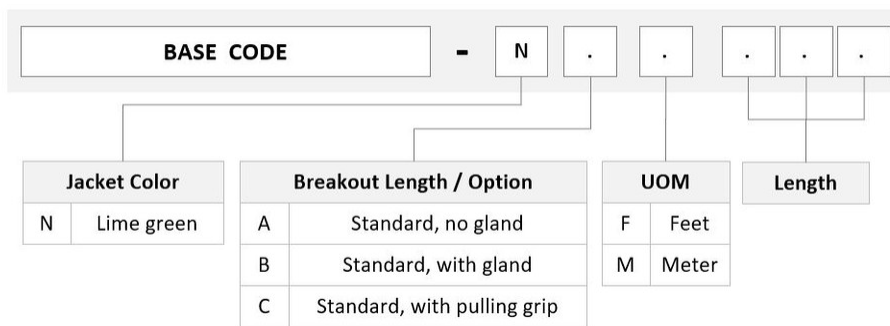

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0° 4.40 lb @ 90°
--	-------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	B2ca
Environmental Space	Indoor Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

F3VMPMPAM

REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760239611 N-144-MP-5G-F12LM/B2	-	Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber, 12 fiber subunits, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color, B2ca Flame rating
860647056	-	MP012, LOW LOSS, FEMALE, OM5, LIME, 3mm