


FAWSCUC01

Base Product

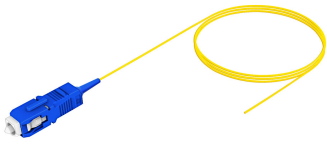

Low Loss Singlemode SC/UPC to Stub, Fiber Pigtail, Simplex 0.9mm, Unrated

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Series	FAW

General Specifications


Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Interface, Connector A	SC/UPC
Jacket Color	Yellow
Polarity	Method B Enhanced
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 20
Cable Assembly Length Range (ft)	1 – 66
Diameter Over Jacket	0.9 mm 0.035 in

Ordering Tree

FAWSCUC01

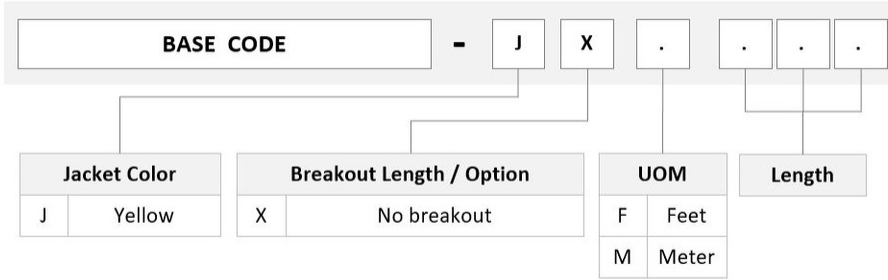

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®
Insertion Loss, maximum, connector A	0.25 dB
Return Loss, minimum, connector A	50 dB

Environmental Specifications

Environmental Space	Unrated
----------------------------	---------

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

Included Products

- 760038570 – TeraSPEED® 900µm Tight Buffered Fiber X-TB-8W-YL-F/G
- 860648962 – SC/UPC Connector, Singlemode, Blue