


FBXL1UC11

Base Product

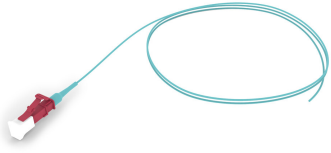

OM4 LC/UPC Keyed Red to Unconnectorized, Fiber Pigtail Simplex, 0.9 mm SBJ

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand Europe Latin America Middle East /Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber pigtail, unjacketed |
| Product Brand | SYSTIMAX InstaPATCH® 360 |
| Product Series | FBX |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |

General Specifications


| | |
|---------------------------------------|--------|
| Color, boot A | Aqua |
| Color, connector A | Red |
| Interface, Connector A | LC/UPC |
| Interface Feature, connector A | Keyed |
| Jacket Color | Aqua |
| Total Fibers, quantity | 1 |

Dimensions

| | |
|---|--------|
| Cable Assembly Length Range (m) | 1 – 20 |
| Cable Assembly Length Range (ft) | 1 – 66 |

Ordering Tree

FBXL1UC11

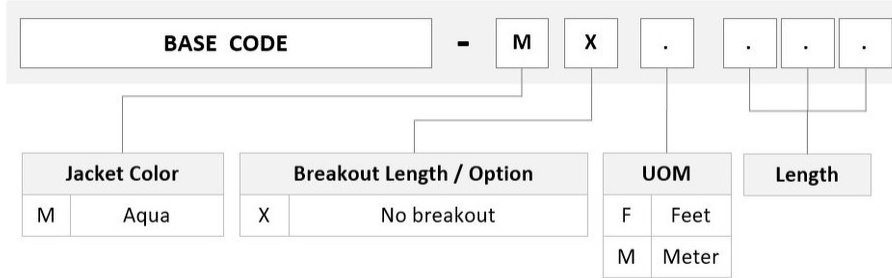

Mechanical Specifications

Cable Retention Strength, maximum 2.00 lb @ 90 ° | 5.00 lb @ 0 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

Included Products

- 760102566 MFC-LCR-09-KRD - LazrSPEED®, OptiSPEED® Pre-Radiused Behind The Wall Keyed LC Connector for 0.9 mm Fiber, multimode, red
- N-001-RF-5K-F09 - Fiber Indoor Cable, LazrSPEED® 0.9 mm Low Smoke Zero Halogen Reinforced Buffered, 1 fiber, Multimode OM4, Gel-free, Meters jacket marking