


FLXMXSCAH

Base Product

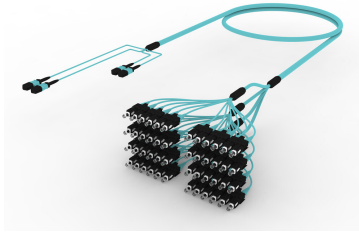

LazrSPEED® 550 MPO (Pinned) to SC/UPC, InstaPATCH® 360 Ruggedized Fanout Cable, 48-Fiber, Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX InstaPATCH® 360

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, connector A

Aqua

Color, connector B

Beige

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

MPO-12/UPC Male

Interface, Connector B

SC/UPC

Jacket Color

Aqua

Polarity

Method B (LL)

Fibers per Subunit, quantity

12

Total Fibers, quantity

48

Dimensions

Cable Assembly Length Range (m)


3 – 999

Cable Assembly Length Range (ft)

7 – 999

Ordering Tree

FLXXMXSCAH

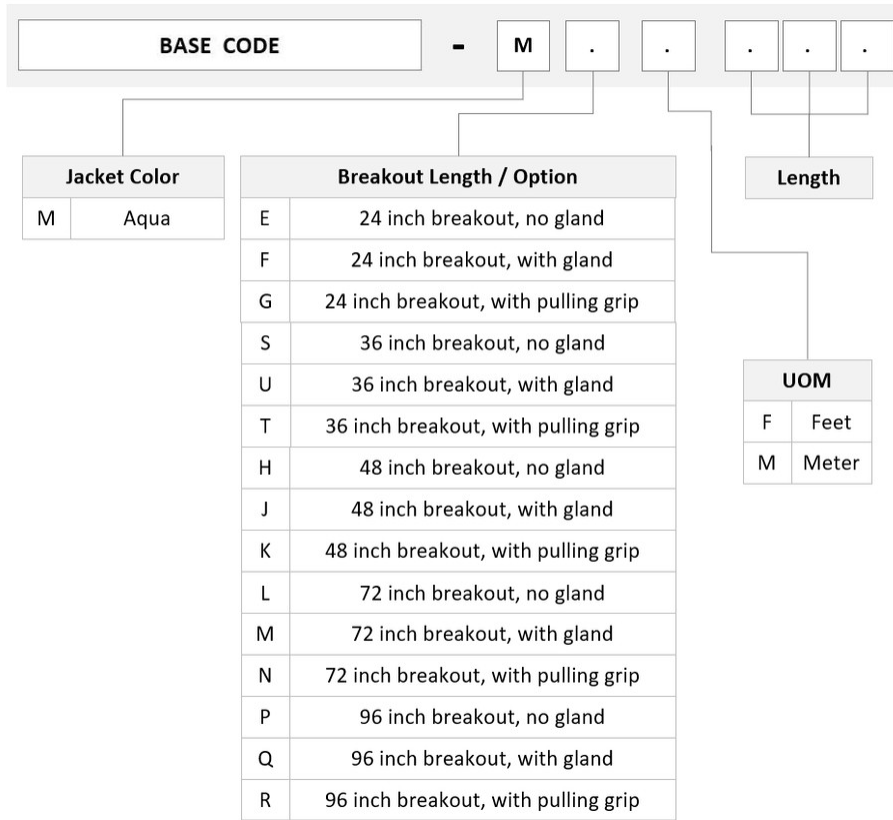

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

FLXMXSCAH

Included Products

- 460125750 – LazrSPEED® Pre-Radiused SC Connector for 1.6 mm Fiber Cordage, Duplex, multimode
- 860647047 – MPO12, LOW LOSS, MALE, OM3/4, AQUA, 3mm
- P-048-MP-5K-F12 – Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 48 fiber multi-unit with 12 fiber subunits, Multimode OM4, Gel-free, Feet jacket marking