


CP7686-000 | OC-ADP-L2-L2-NFCD

Fiber Optic Adapter, Duplex, LC/APC, Green, Zirconia

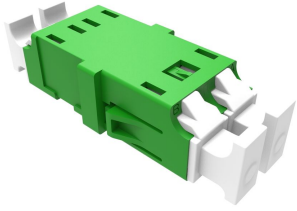

Product Classification

Regional Availability	Asia EMEA North America
Product Type	Fiber adapter
Product Series	OC-ADP


General Specifications

Body Style	Duplex
Color	Green
Interface	LC/APC
Mounting	Square flange
Shuttered	No
Total Ports, quantity	2
Transmission Standards	IEC 60754-1 IEC 61300-3-42

Dimensions

Height	9.3 mm 0.366 in
Width	12.8 mm 0.504 in
Length	29.3 mm 1.154 in

Outline Drawing

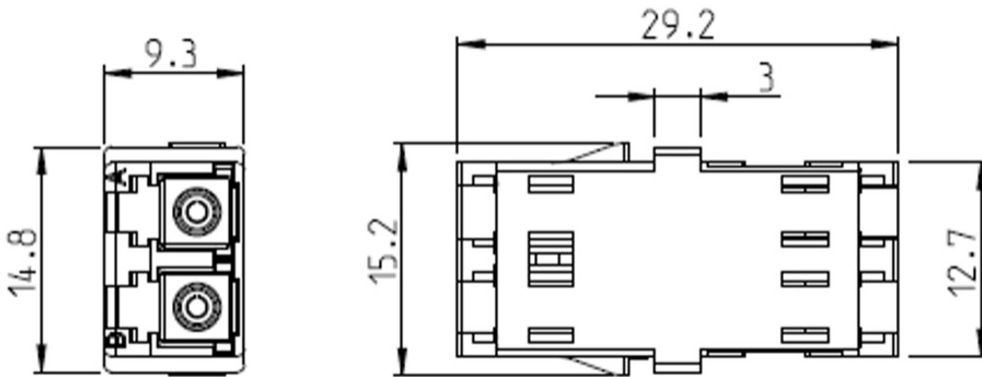

Material Specifications

Alignment Sleeve Material Zirconia (ceramic)

Mechanical Specifications

Coupling Retention Force 70 N | 15.737 lbf

Optical Specifications

Fiber Mode Singlemode

Insertion Loss, Splitter, maximum 0.1 dB

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

