

F1A-HRNF-4M

FSJ1-50A SureFlex® Jumper with interface types N Female and 4.3-10 Male Right Angle, 4 m



- WARNING: DO NOT MATE WITH 4.1-9.5 DIN

Product Classification

Product Type SureFlex® standard

Product Series FSJ1-50A

General Specifications

Body Style, Connector A Straight

Body Style, Connector B Right angle

Interface, Connector A N Female

Interface, Connector B 4.3-10 Male

Specification Sheet Revision Level A

Dimensions

Length 4 m | 13.123 ft


Nominal Size 1/4 in

VSWR/Return Loss

Frequency Band	VSWR	Return Loss (dB)
700–3000 MHz	1.44	15

Jumper Assembly Sample Label

F1A-HRNF-4M

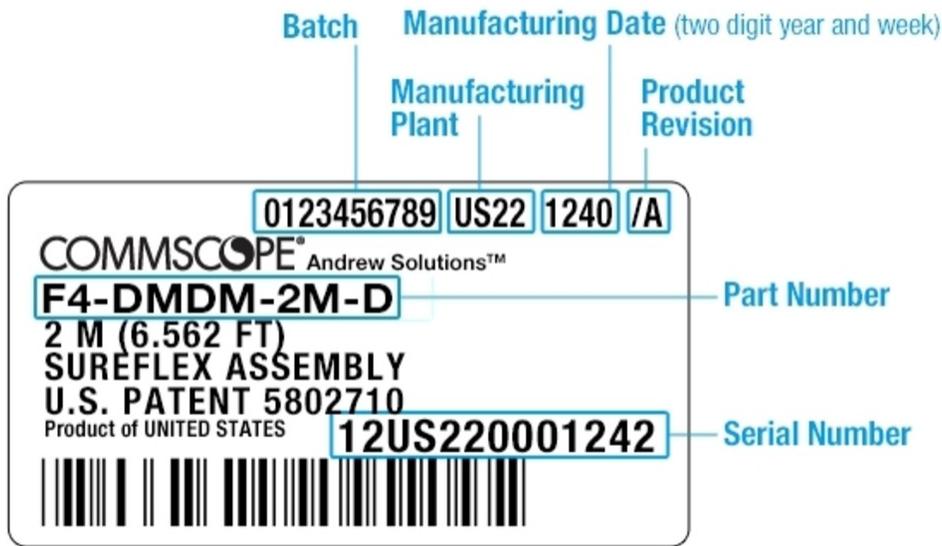

Environmental Specifications

Immersion Test Method

Meets IEC 60529:2001, IP68 in mated condition

Included Products

- F1TNF-LS - Type N Female for 1/4 in foam and air coaxial cable, factory attached
- FSJ1-50A - FSJ1-50A, HELIAX® Superflexible Low Density Foam Coaxial Cable, corrugated copper, 1/4 in, black PE jacket