


# FGS-MH4E-H-VS

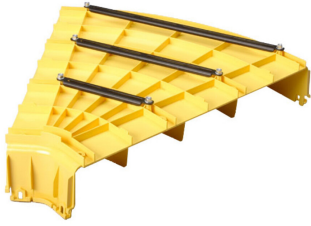

FiberGuide® Variable Support Bracket Kit for 4x24in Horizontal Elbow

## Product Classification

|                              |   |
|------------------------------|---|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   EMEA   Latin America   North America |
| <b>Portfolio</b>             | CommScope®  |
| <b>Product Type</b>          | Support mounting kit  |
| <b>Product Brand</b>         | FiberGuide®   |
| <b>Product Series</b>        | FGS   |

## General Specifications

|                     |            |
|---------------------|------------|
| <b>Color</b>        | Yellow     |
| <b>Orientation</b>  | Horizontal |
| <b>Section Type</b> | Bracket    |

## Dimensions

|                          |                                |
|--------------------------|--------------------------------|
| <b>System Dimensions</b> | 102 mm x 610 mm (4 in x 24 in) |
|--------------------------|--------------------------------|

## Ordering Tree

|     |    |   |      |   |   |
|-----|----|---|------|---|---|
| 9   | 10 |   |      |   |   |
| FGS | B  | - | MH4E | - | A |

### Section Color

|   |       |        |
|---|-------|--------|
| 9 | empty | yellow |
|   | B     | black  |

\* Support brackets only come in black

### Section Size

|    |      |                                     |
|----|------|-------------------------------------|
| 10 | A    | 4 x 4 in                            |
|    | B    | 4 x 6 in                            |
|    | F    | 4 x 12 in                           |
|    | G    | 2 x 6 in                            |
|    | H    | 4 x 24 in                           |
|    | H-VS | 4 x 24 in, variable support bracket |

## Material Specifications

# FGS-MH4E-H-VS

---

**Material Type** Engineering Thermoplastic

## Environmental Specifications

**Flammability Rating** CSA S143 | UL 2024 | UL 94 V-0

**Halogen Characteristics** Blue Angel | TCO '99 | WEEE

**Safety Standard** CSA | UL

## Packaging and Weights

**Weight, net** 0.875 kg | 1.929 lb

## Regulatory Compliance/Certifications

| Agency     | Classification   |
|------------|--|
| CHINA-ROHS | Below maximum concentration value  |
| REACH-SVHC | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS       | Compliant  |
| UK-ROHS    | Compliant  |

