


760251230 | FACT-MMDR5H-A

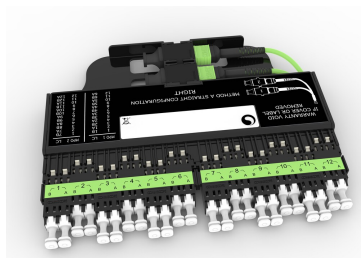

FACT® MPO Module, right sided, LC at front side, 2x12 fiber MPO at rear side, Ultra Low Loss (ULL) multimode OM5, wiring method A straight

- Offers the same craft-friendly interface for LC and SC connectors as the cabled module
- Allow installers to connect an MPO trunk cable to turn up services in rapid installation applications

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber module |
| Product Brand | FACT® |
| Product Series | FACT |

General Specifications

| | |
|-------------------------------------|---|
| Functionality | Breakout |
| Application | For Use with FACT NG4 Universal Chassis |
| Body Style | Right orientation |
| Color, boot | Black |
| Color, housing | Black |
| Color, rear | Lime green |
| Interface, front | LC/UPC |
| Interface Feature, front | Duplex |
| Interface Color, front | Lime green |
| Interface, rear | MPO |
| Interface Feature, rear | Female Key up/down Pinned |
| Interface Color, rear | Lime green |
| Polarity | Method A |
| Total Fibers, quantity | 24 |
| Total Ports, quantity, front | 12 |
| Total Ports, quantity, rear | 2 |

Dimensions

760251230 | FACT-MMDR5H-A

| | |
|---------------|---------------------|
| Height | 13.21 mm 0.52 in |
| Width | 159.77 mm 6.29 in |
| Depth | 122.68 mm 4.83 in |

Optical Specifications

| | |
|--------------------------------|-----------|
| Fiber Mode | Multimode |
| Fiber Type | OM5 |
| Insertion Loss, maximum | 0.4 dB |
| Insertion Loss, typical | 0.32 dB |
| Return Loss, minimum | 27 dB |

Environmental Specifications

| | |
|------------------------------|-------------------------------------|
| Operating Temperature | -5 °C to +40 °C (+23 °F to +104 °F) |
| Storage Temperature | -5 °C to +50 °C (+23 °F to +122 °F) |
| Relative Humidity | Up to 85%, non-condensing |

Packaging and Weights

| | |
|---------------------------|--------------|
| Packaging quantity | 1 |
| Packaging Type | Bag Carton |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|-----------------------------------|
| CHINA-ROHS | Above maximum concentration value |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

