


# URGQPQXHF

## Base Product

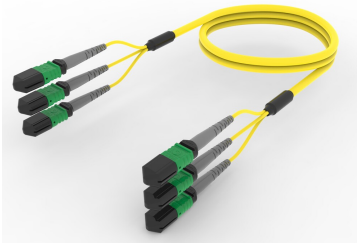

Ultra Low Loss (ULL) Singlemode, MPO/8(Unpinned) to MPO/8(Pinned), 24-Fiber, LSZH,array cord

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber array cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	3
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	3
<b>Color, boot B</b>	Gray
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-08/APC Female
<b>Interface Feature, connector A</b>	Unpinned
<b>Interface, Connector B</b>	MPO-08/APC Male
<b>Interface Feature, connector B</b>	Pinned
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	24


# URGPQXHF

## Dimensions

**Cable Assembly Length Range (m)** 1 – 305

**Cable Assembly Length Range (ft)** 1 – 999

## Ordering Tree

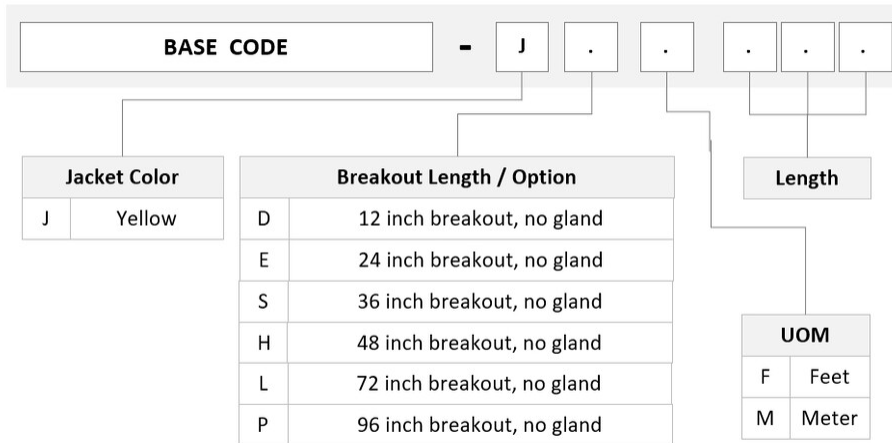

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# URGQPQXHF

---

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



## Included Products

- 760238981 N-024-MP-8G-F24YL/D – Low Smoke Zero Halogen Riser MPO Trunk Cable, 24 fiber
- 860637705 – MPO8, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm
- 860637706 – MPO8, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm