


UNXLCUCC6

Base Product

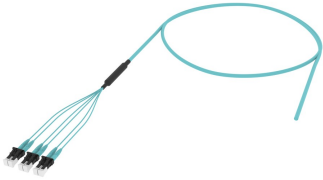

Ultra Low Loss ULL LazrSPEED® 550 LC/UPC to Unconnectorized, Ruggedized fanout Cable, 6-Fiber, LSZH, PmP 2.0 mm Dca Cable

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Blue
Color, connector A	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	LC/UPC
Interface Feature, connector A	ULL
Interface, Connector B	Unterminated
Jacket Color	Aqua
Fibers per Subunit, quantity	6
Total Fibers, quantity	6

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

UNXLCUCC6

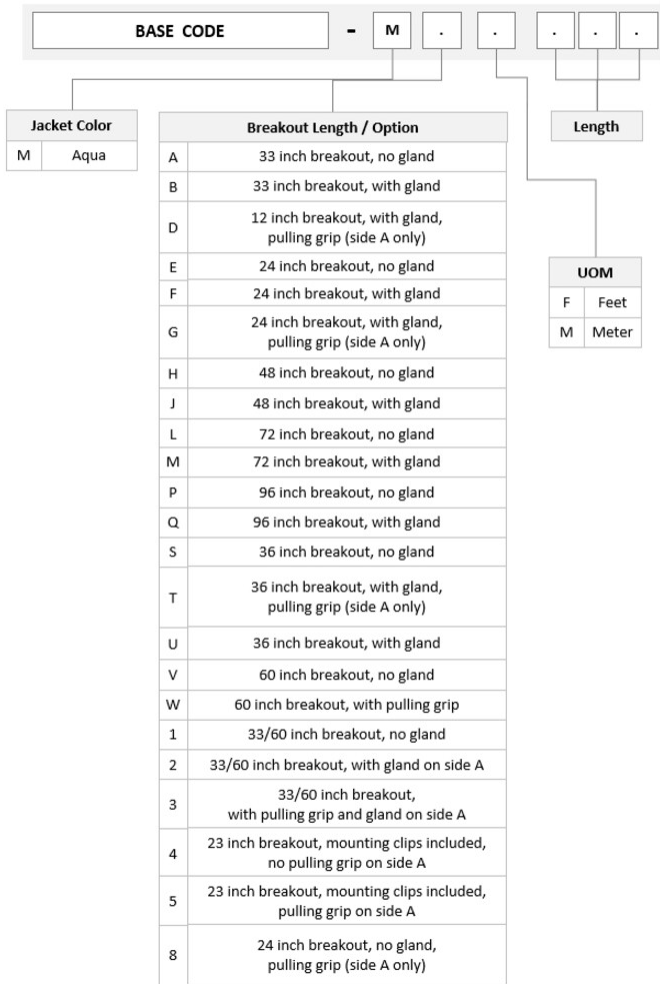

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	Dca
Environmental Space	Dual Rated LSZH/Riser Indoor

Included Products

760222844 N-012-MP-5K-F12AQ/20T/D	-	Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk with 2.0mm
--------------------------------------	---	--

UNXLCUCC6

Subunits, 12 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca flame rating