


BLK-RCT-A18D0

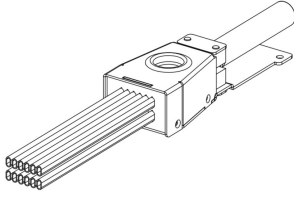

Fiber Optic Ribbon Breakout Kit, 1-12F/ribbon, 240-432F/tube, 11-15 mm central tube outside dia., 18 tubes/leg

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber breakout kit, rectangular
Product Series	BLK-R

General Specifications

Application	For use with ribbon fiber cables
Breakout Legs, quantity	1
Fibers per Ribbon, maximum	12
Fibers per Tube, maximum	672
Tube Type	Ribbon central tube
Tubes per Leg, quantity	18

Dimensions

Tube Length	5,001.26 mm 196.9 in
Central Tube Outer Diameter	11 mm – 15 mm (0.43 in – 0.60 in)

Environmental Specifications

Environmental Space	Outdoor
----------------------------	---------

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

BLK-RCT-A18D0

ROHS

Compliant

UK-ROHS

Compliant

