


FPCH

Base Product

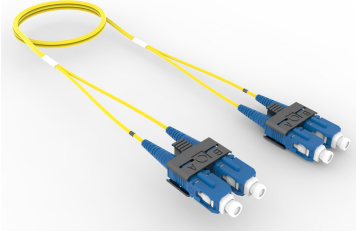

Fiber Optic Patch Cord, Duplex, Singlemode, 1.2 mm OFNP and LSZH jacket, tuned

- SC/UPC, SC/APC, LC/UPC and LC/APC connector versions
- Reduced Bend Radius fiber allows routing in electronic equipment cabinets or bays that commonly provide minimal cable management features
- Compatible with industry standard fiber cable and SC and LC connectors
- G.657.A2 rated glass
- High quality connectors
- OFNP cable

1.2 mm fiber optic patch cord assemblies, designed and tested to Telcordia GR409 requirements for small form factor cables, and GR-326 CORE mechanical and performance requirements. Also, designed and tested to the intermateability requirements of IEC 61754-4 and TIA-604-3-B.

Product Classification

Regional Availability	Europe Latin America Middle East/Africa North America
Product Type	Fiber patch cord, duplex
Product Series	FPCH


General Specifications

Jacket Color	Yellow
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	1 – 99
Cable Assembly Length Range (ft)	1 – 325
Diameter Over Jacket	1.2 mm 0.047 in

Ordering Tree

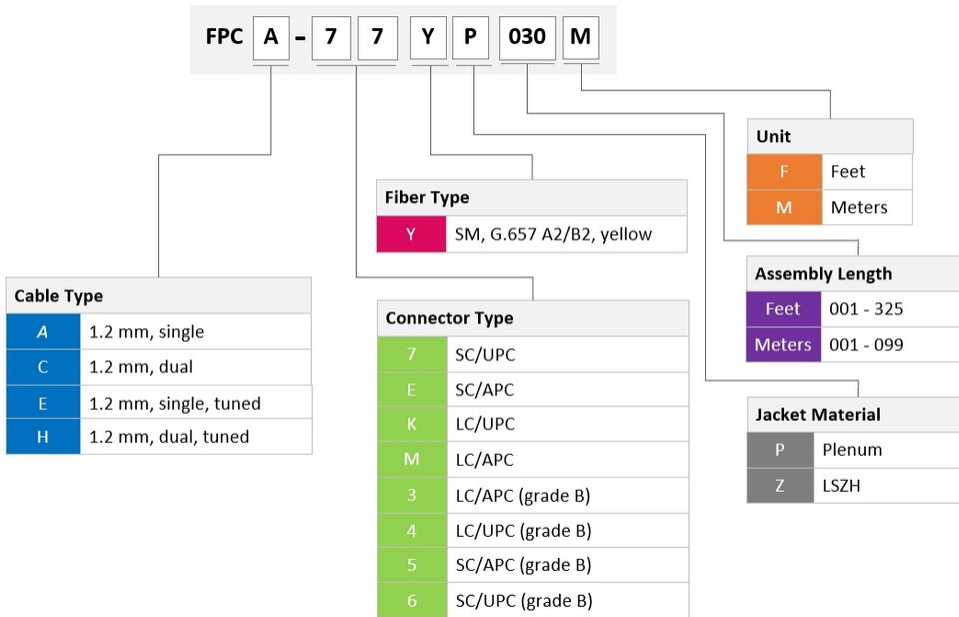

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2/B2

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

