


PGP-CS08

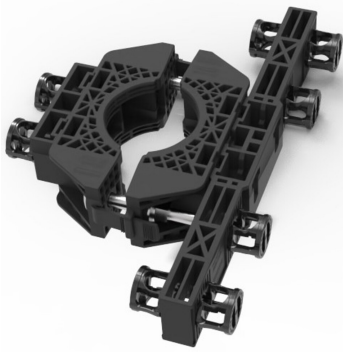

Polymer PIM-Guard® Antenna and RRU Cable Support Bracket with 8 positions / 16 cables for stackable hangers (up to 2 per position)

Compatible with first and second generation Polymer PIM-Guard products
-SSH-1416
-SSH-411
-SSH-1117

Product Classification

Product Type Antenna/RRU Cable Support
Product Brand PIM-Guard®

General Specifications


Cable Runs, quantity 8
Hole, quantity 8
Mounting Round member

Dimensions

Height 50.8 mm | 2 in
Width 304.8 mm | 12 in
Length 152.4 mm | 6 in
Mounting Diameter, maximum 76.2 mm | 3 in
Mounting Diameter, minimum 60.96 mm | 2.4 in
Hole Size 3/4 in

Ordering Tree

PGP-CS08

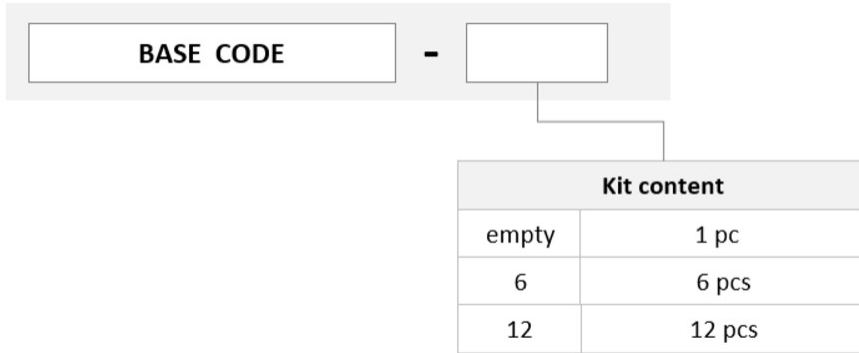

Material Specifications

Material Type Polymer

Packaging and Weights

Packaging quantity 1

Weight, net 0.7 kg | 1.543 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

