


760250062 | OCP-EC-26DASQI-XX

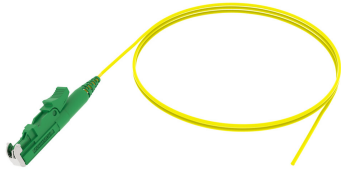

Fiber Optic Pigtail, Simplex, Singlemode, LSZH, 1.8 mm diameter, tuned, Grade B, LSH/APC to Stub, yellow, 26 m

Product Classification

| | |
|------------------------------|-------------------------|
| Regional Availability | EMEA |
| Product Type | Fiber pigtail, jacketed |
| Product Series | OCP |

General Specifications

| | |
|-------------------------------|---------|
| Connector A, quantity | 1 |
| Color, boot A | Green |
| Color, connector A | Green |
| Interface, Connector A | LSH/APC |
| Jacket Color | Yellow |
| Total Fibers, quantity | 1 |

Dimensions

| | |
|-----------------------------|-------------------|
| Cord Length | 26 m 85.302 ft |
| Diameter Over Jacket | 1.8 mm 0.071 in |

Optical Specifications

| | |
|---|----------------------|
| Fiber Mode | Singlemode |
| Fiber Type | G.657.A1, TeraSPEED® |
| Performance Grade | Superior B grade |
| Insertion Loss, maximum, connector A | 0.25 dB |
| Return Loss, minimum, connector A | 60 dB |

Environmental Specifications

| | |
|----------------------------|-------------------------------|
| Environmental Space | Low Smoke Zero Halogen (LSZH) |
|----------------------------|-------------------------------|

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



* Footnotes

Performance Grade Guarantee to meet IEC 61755-1 Random Mating requirement