


# PML-SU4-B

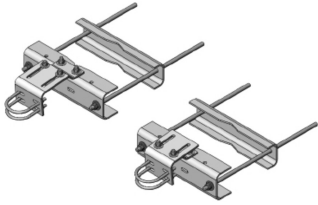

## Large Leg Universal Sliding Pipe Mount Kit for 4-1/2 in OD pipe

### Product Classification

**Product Type** Pipe mount

### General Specifications

**Mounting** Angle 60°, 406.4 mm (16 in) | Angle 90°, 304.8 mm (12 in) | Straight or tapered legs up to 406.4 mm (16 in) OD

**Note** One 8 ft microwave antenna with stiff arm

**Pipe, quantity** 0

**Tower Taper** Non-tapered | Tapered

### Dimensions

**Height** 127 mm | 5 in

**Width** 304.8 mm | 12 in

**Length** 304.8 mm | 12 in

**Mounting Diameter, maximum** 406.4 mm | 16 in

**Mounting Diameter, minimum** 0 mm | 0 in

**Pipe Outer Diameter** 114.3 mm | 4.5 in

**Stand-off Distance** 203.2 mm | 8 in

### Material Specifications

**Material Type** Hot dip galvanized steel

### Mechanical Specifications

**Wind Rating** 120 mph (BWS) at 150 ft AGL

**Wind Rating Test Method** TIA/EIA-222

### Packaging and Weights

**Included** Sliding pipe mount brackets | Universal saddle mount

# PML-SU4-B

---

**Packaging quantity** 1  
**Weight, net** 36.8 kg | 81.13 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## \* Footnotes

**Wind Rating** BWS—Base Wind Speed; FBC—Florida Building Code