


FD5M-864S00DEB5

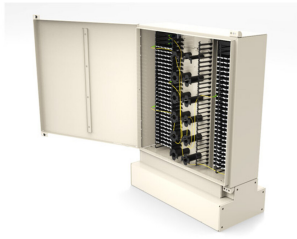

FDH5000 cabinet with 864 ports, LC/APC, no splitters, dry dielectric flat ribbon, 100 ft stub, 144F feeder, 2x 432F distribution, pad mount with 8 in riser

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber distribution hub
Product Series	FDH 5000

General Specifications

Access	Front
Cable Type	Pigtails - Ribbon
Color	Putty white
Distribution Cables, quantity	2
Distribution Ports, quantity	864
Fibers per Distribution Cable, quantity	432
Fibers per Feeder Cable, quantity	144
Mounting	Pad
Splitter Slots, quantity	9

Dimensions

Height	901.7 mm 35.5 in
Width	698.5 mm 27.5 in
Depth	330.2 mm 13 in
Cable Length	30.48 m 100 ft
Enclosure Size	Large

Material Specifications

Finish	Powder coated
Material Type	Steel

FD5M-864S00DEB5

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

