


F-CLAMP-A2CC-4B

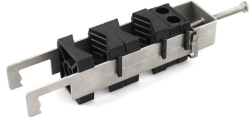

KwikClamp™ Hanger for power & fiber cables, one 4.5-9 mm hole and one 22-34 mm hole (alongside each other), quadruple block; includes hardware

Product Classification

Product Type	Hanger kit
Product Brand	KwikClamp™
Ordering Note	CommScope® standard product in Europe, the Middle East, and Africa Minimum order quantity (MOQ) is 1 box

General Specifications

Cables per Hanger	2
Color	Black
Hanger Type	KwikClamp™ hanger
Mounting	3-25 mm angle iron 3-25 mm flat plate Round Member 8-25 mm

Dimensions

Maximum Stack Height	4
Height	224 mm 8.819 in
Width	44 mm 1.732 in
Length	45 mm 1.772 in
Compatible Cable Diameter Range	22-34 mm 7-9 mm
Diameter Range (cable 1)	7-9 mm
Diameter Range (cable 2)	22-34 mm
Hanger Spacing, maximum	1.83 m 6.004 ft

Electrical Specifications

Return Loss Effect, maximum	0.1 dB
DTF Effect, maximum	0.1 dB

F-CLAMP-A2CC-4B

Material Specifications

Material Type EPDM rubber | Engineered plastic | Stainless steel

Mechanical Specifications

Vibration Survival ≥4 hours at resonant frequency

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Corrosion Resistance, minimum with no degradation ≥500 hours in salt spray chamber

Environmental Strength Capability Five times cable weight

UV Resistance, minimum with no degradation ≥124 hours exposure in accelerated UV life chamber, testing duration 1344 hrs

Packaging and Weights

Height, packed 15.5 cm | 6.102 in

Width, packed 30.5 cm | 12.008 in

Length, packed 35.5 cm | 13.976 in

Included Hardware

Packaging quantity 24

Weight, gross 6 kg | 13.228 lb

* Footnotes

Maximum Stack Height Fiber, Hybrid, Power