


2105082-3

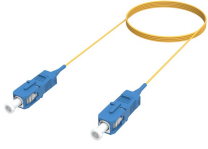

Fiber Optic Patch Cord, Simplex, 0.9mm, LSZH, Singlemode, SC/UPC to SC/UPC, Yellow, 3 m

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand China India |
| Portfolio | CommScope® |
| Product Type | Fiber patch cord, simplex |
| Product Series | 210 |

General Specifications


| | |
|-------------------------------|--------|
| Connector A, quantity | 1 |
| Color, boot A | Blue |
| Color, connector A | Blue |
| Connector B, quantity | 1 |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Interface, Connector A | SC/UPC |
| Interface, Connector B | SC/UPC |
| Jacket Color | Yellow |
| Total Fibers, quantity | 1 |

Dimensions

| | |
|-----------------------------|-------------------|
| Cord Length | 3 m 9.843 ft |
| Diameter Over Jacket | 0.9 mm 0.035 in |

Ordering Tree

 2105082-3



| Examples of Lengths (meters) | |
|------------------------------|-----------|
| -1 | 1 meters |
| -2 | 2 meters |
| -3 | 3 meters |
| 1- -0 | 10 meters |

Mechanical Specifications

Cable Retention Strength, maximum 1.00 lb @ 0° | 1.00 lb @ 90°

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A1, TeraSPEED®
Insertion Loss, maximum 0.25 dB
Return Loss, minimum 50 dB

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|---|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



