


FGS-MHRT-H/M

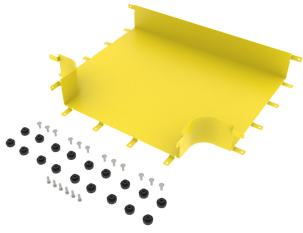

FiberGuide® Horizontal T, 4x24in, 4x18in Exit, Yellow

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Tee
Product Brand	FiberGuide®
Product Series	FGS

General Specifications

Product Feature	Transition
Color	Yellow
Orientation	Horizontal
Section Type	Tee section

Dimensions

Height	114 mm 4.488 in
Width	628 mm 24.724 in
Length	753 mm 29.646 in
System Dimensions	102 mm x 457 mm (4 in x 18 in) 102 mm x 610 mm (4 in x 24 in)

Ordering Tree

FGS-MHRT-H/M

9 10
 FGS B - MHRT - H

Section Color

9	empty	yellow
	B	black

Section Size

10	A	4 x 4 in
	B	4 x 6 in
	B-VS	4 x 6 in, variable support bracket
	F	4 x 12 in
	F/B	4 x 12 in, 6 in exit
	F/B-S	4 x 12 in, 6 in exit, with variable support bracket
	F/B-VS	4 x 12 in, 6 in exit, variable support bracket
	F-VS	4 x 12 in, variable support bracket
	G	2 x 6 in
	H	4 x 24 in
	H/F	4 x 24 in, 12 in exit
	H/F-VS	4 x 24 in, 12 in exit, variable support bracket
	M	4 x 18 in
	M/F	4 x 18 in, 12 in exit
	M/H	4 x 18 in, 24 in exit
	H/M	4 x 18 in

* Support brackets only come in black

Material Specifications

Material Type Steel

Environmental Specifications

Safety Standard CSA | UL

Packaging and Weights

Weight, net 2.85 kg | 6.283 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

